


I-SYS IK-100/101 Swaged External Threads fitted on both ends

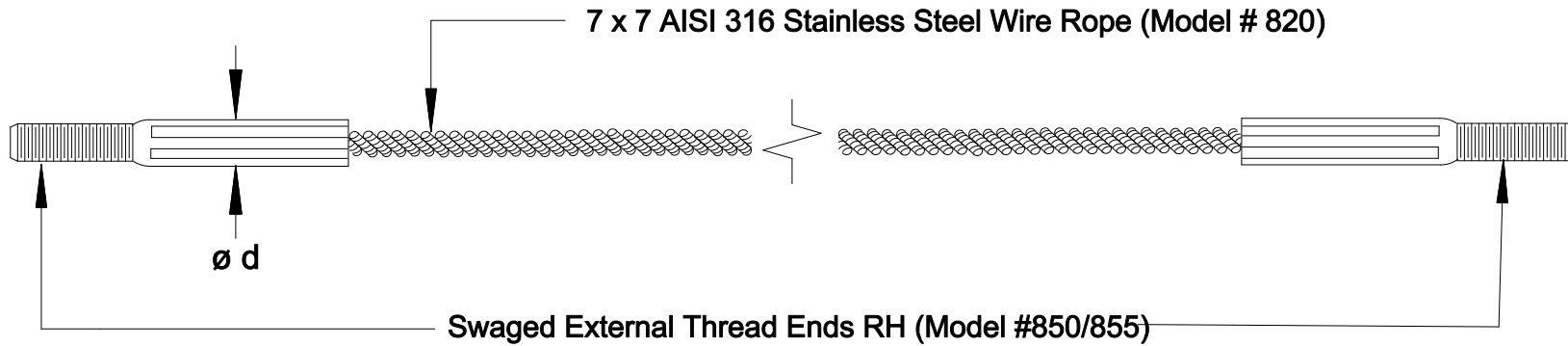

I-SYS
IK 100/101
Stainless
Steel wire
rope
assembly

Part Number	\varnothing Rope	Thread size/length	$\varnothing d$
IK 100-0200	2 mm	M5 x 30 mm	5 mm
IK 100-0201	2 mm	M5 x 60 mm	5 mm
IK 100-0300	3 mm	M6 x 30 mm	6 mm
IK 100-0301	3 mm	M6 x 60 mm	6 mm
IK 100-0400	4 mm	M6 x 30 mm	7 mm
IK 100-0401	4 mm	M6 x 60 mm	7 mm
IK 100-0500	5 mm	M8 x 30 mm	8 mm
IK 100-0501	5 mm	M8 x 60 mm	8 mm
IK 100-0600	6 mm	M10 x 30 mm	10 mm
IK 100-0601	6 mm	M10 x 60 mm	10 mm
IK 100-0800	8 mm	M12 x 80 mm	13 mm
IK 100-1000	10 mm	M16 x 115 mm	18 mm
IK 100-1200	12 mm	M20 x 130 mm	20 mm
IK 100-1600	16 mm	M24 x 160 mm	27 mm
IK 100-2000	20 mm	M30 x 200 mm	32 mm

**IK-100/101 External Swaged External Threads
fitted on both ends**
Each assembly consists of;

(variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
(2 qty.) -Swaged External Thread Ends RH (Model #850/855)
Available in a RH/LH combination (IK101)

Metric Fittings.
Measurements given
in Millimeters.

