


I-SYS IK-110 Swage & External Thread Turnbuckle Fitted each end

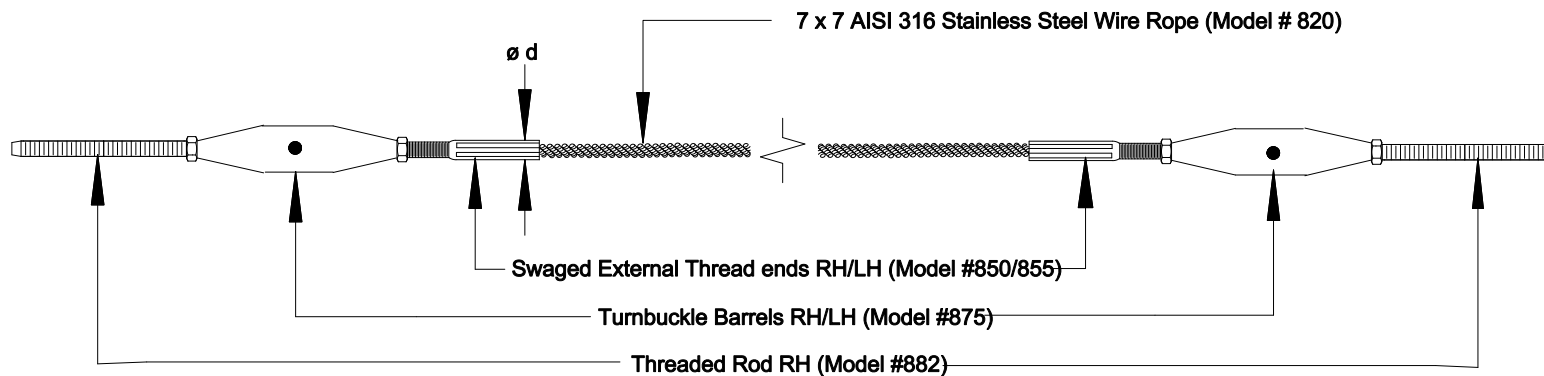

I-SYS
IK 110 Stainless
Steel wire
rope
assembly

Part Number	\varnothing Rope	Thread size/length	Adjustment in mm	$\varnothing d$
IK 110-0200	2 mm	M5 x 60mm	+52/-86	5 mm
IK 110-0300	3 mm	M6 x 60mm	+56/-100	6 mm
IK 110-0400	4 mm	M6 x 60mm	+56/-100	7 mm
IK 110-0500	5 mm	M8 x 60mm	+68/-100	8 mm
IK 110-0600	6 mm	M10 x 60mm	+60/-100	10 mm
IK 110-0800	8 mm	M12 x 60mm	+92/-140	13 mm
IK 100-1000	10 mm	M16 x 60mm	+96/-180	18 mm
IK 110-1200	12 mm	M20 x 60mm	+120/-210	20 mm
IK 110-1600	16 mm	M24 x 60mm	+180/-240	27 mm

I-SYS IK-110 Swage & External Thread Turnbuckle Fitted each end

Each assembly consists of;

- (variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
- (2 qty.) -Swaged External Thread Ends RH/LH (Model # 850/855)
- (2 qty.) -Turnbuckle Barrels RH/LH (Model # 875)
- (4 qty.) -Hexagon Nuts RH/LH (Model # 892/893)
- (2 qty.) -Threaded Rod RH (882)

Metric Fittings.
Measurements given
in Millimeters.

