


I-SYS IK-120/121 F30 Hammer Swage fitted on both ends

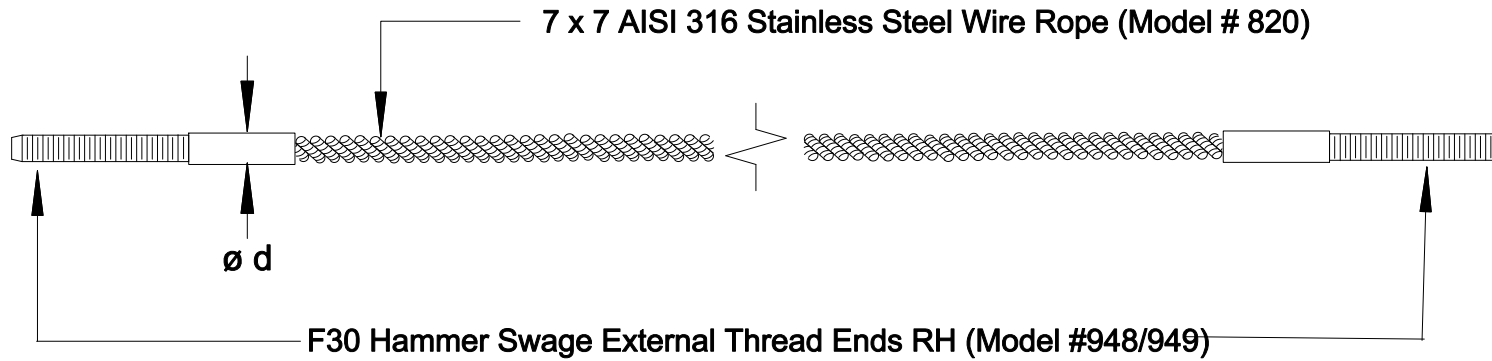

I-SYS
IK 120/121
Stainless
Steel wire
rope
assembly

Part Number	ø Rope	Thread size/length	ø d
IK 120-0300	3 mm	M4 x 20 mm	3,9 mm
IK 120-0301	3 mm	M4 x 40 mm	3,9 mm
IK 120-0400	4 mm	M5 x 30 mm	4,9 mm
IK 120-0401	4 mm	M5 x 50 mm	4,9 mm
IK 120-0500	5 mm	M6 x 30 mm	5,9 mm
IK 120-0501	5 mm	M6 x 50 mm	5,9 mm
IK 120-0600	6 mm	M8 x 30 mm	7,9 mm
IK 120-0601	6 mm	M8 x 60 mm	7,9 mm
IK 120-0800	8 mm	M10 x 30 mm	9,9 mm
IK 120-0801	8 mm	M10 x 60 mm	9,9 mm
IK 120-1000	10 mm	M12 x 30 mm	11,9 mm
IK 120-1001	10 mm	M12 x 60 mm	11,9 mm

**I-SYS IK-120/121 F30 Hammer Swage
fitted on both ends**
Each assembly consists of;

(variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
(2 qty.) -F30 Hammer Swage External Thread Ends RH (Model #948/949)
Available in a RH/LH combination (IK121)

Metric Fittings.
Measurements given
in Millimeters.

