


# I-SYS IK-200/201 Swaged External Threads fitted on both ends

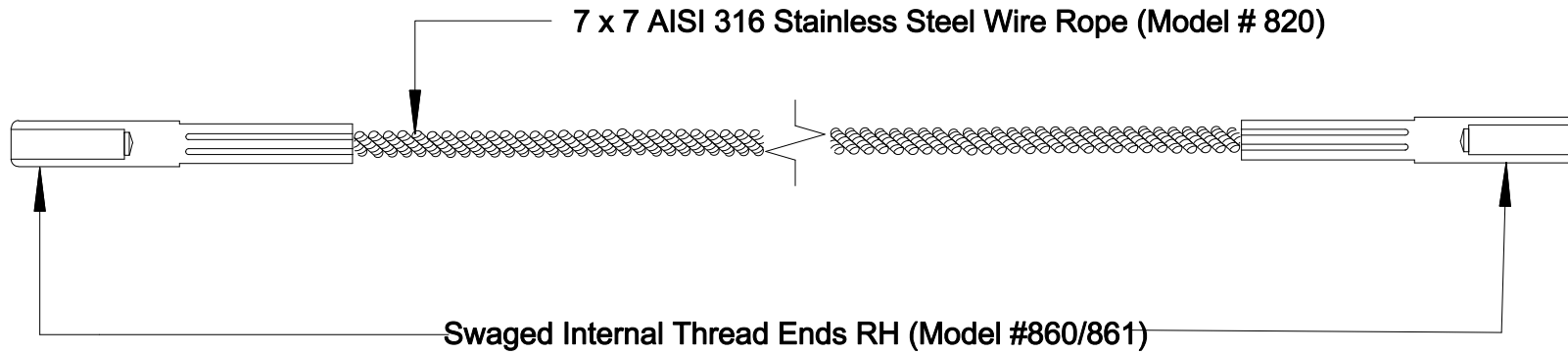

I-SYS  
IK 200/201  
Stainless  
Steel wire  
rope  
assembly

Part Number	∅ Rope	Thread size/length
IK 200-0200	2 mm	M4 x 15 mm
IK 200-0300	3 mm	M5 x 20 mm
IK 200-0301	3 mm	M5 x 35 mm
IK 200-0400	4 mm	M6 x 20 mm
IK 200-0401	4 mm	M6 x 35 mm
IK 200-0500	5 mm	M6 x 20 mm
IK 200-0501	5 mm	M6 x 35 mm
IK 200-0600	6 mm	M8 x 25 mm
IK 200-0601	6 mm	M8 x 50 mm
IK 200-0800	8 mm	M10 x 60 mm
IK 200-1000	10 mm	M12 x 80 mm
IK 200-1200	12 mm	M16 x 100 mm
IK 200-1600	16 mm	M20 x 120 mm

**IK-200/201 External Swaged Internal Threads  
fitted on both ends**  
Each assembly consists of;

(variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)  
(2 qty.) -Swaged Internal Thread Ends RH (Model #860/861)  
Available in a RH/LH combination (IK 201)

Metric Fittings.  
Measurements given  
in Millimeters.

