


I-SYS IK-320 Swage & Fork Turnbuckle Fitted at Each End

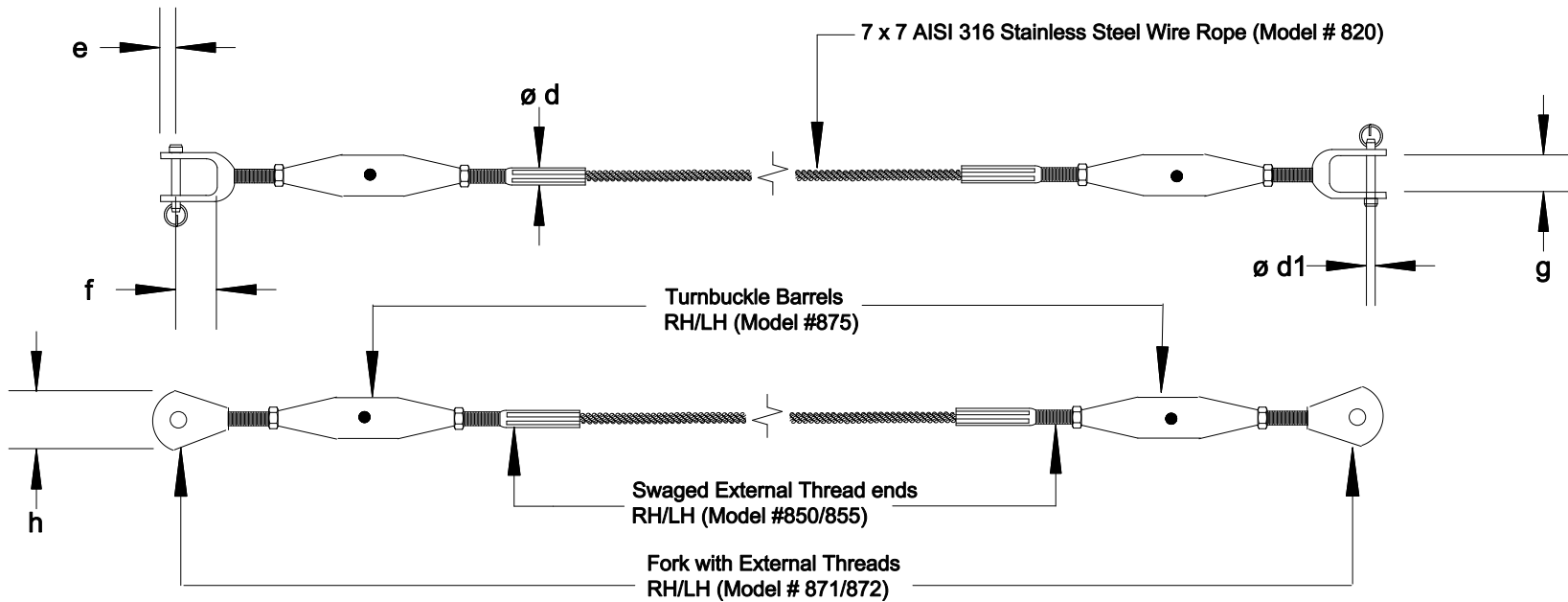

I-SYS
IK 320 Stainless
Steel wire
rope
assembly

Part Number	\varnothing Rope	Thread size/length	Adjustment in mm	$\varnothing d$	$\varnothing d1$	e	f	g	h
IK 320-0200	2 mm	M5	+52/-86	5 mm	5 mm	6 mm	12 mm	7,5 mm	12,5 mm
IK 320-0300	3 mm	M6	+56/-100	6 mm	5 mm	6 mm	12 mm	7,5 mm	12,5 mm
IK 320-0400	4 mm	M6	+56/-100	7 mm	5 mm	6 mm	12 mm	7,5 mm	12,5 mm
IK 320-0401	4 mm	M8	+68/-100	8 mm	6 mm	7 mm	13 mm	10 mm	14,5 mm
IK 320-0500	5 mm	M8	+68/-100	8 mm	6 mm	7 mm	13 mm	10 mm	14,5 mm
IK 320-0600	6 mm	M10	+60/-100	10 mm	8 mm	9 mm	15 mm	11 mm	18 mm
IK 320-0800	8 mm	M12	+92/-140	13 mm	12 mm	14 mm	25 mm	14 mm	26 mm
IK 320-1000	10 mm	M16	+96/-180	18 mm	14 mm	18 mm	31 mm	22 mm	34 mm
IK 320-1200	12 mm	M20	+120/-210	20 mm	19 mm	22 mm	50,5 mm	24 mm	43 mm
IK 320-1600	16 mm	M24	+180/-240	27 mm	25 mm	28 mm	62 mm	30 mm	57 mm

I-SYS IK-320 Swage & Fork Turnbuckle Fitted at Each End

Each assembly consists of;

- (variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
- (2 qty.) -Swaged External Thread Ends RH/LH (Model # 850/855)
- (2 qty.) -Fork with External Threads RH/LH (Model # 871/872)
- (4 qty.) -Hexagon Nuts RH/LH (Model # 892/893)
- (2 qty.) -Turnbuckle Barrels RH/LH (Model # 875)

Metric Fittings.
Measurements given
in Millimeters.

