


# I-SYS IK-420 Swage & Eye Turnbuckle Fitted at Each End

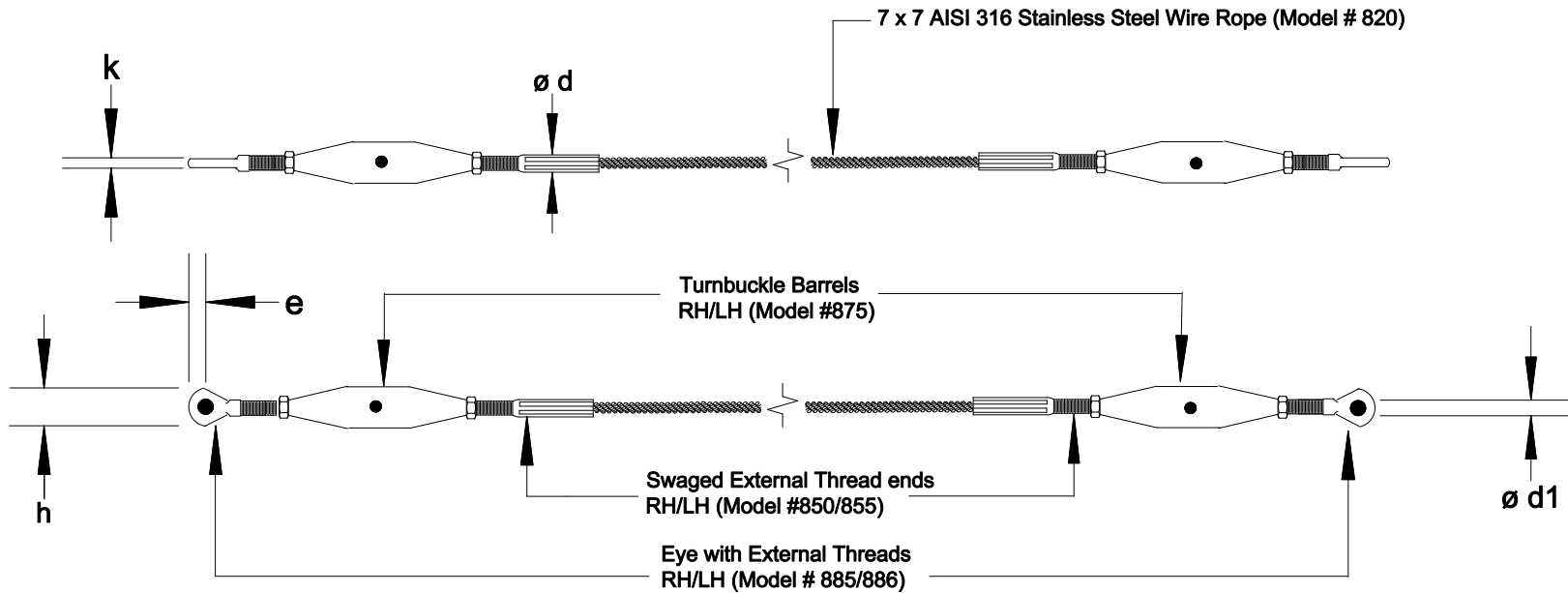

I-SYS  
IK 420 Stainless  
Steel wire  
rope  
assembly

Part Number	$\varnothing$ Rope	Thread size/length	Adjustment in mm	$\varnothing d$	$\varnothing d1$	e	h	k
IK 420-0200	2 mm	M5	+52/-86	5 mm	5,5 mm	6 mm	12 mm	3 mm
IK 420-0300	3 mm	M6	+56/-100	6 mm	6,5 mm	7 mm	14 mm	4 mm
IK 420-0400	4 mm	M6	+56/-100	6 mm	6,5 mm	7 mm	14 mm	4 mm
IK 420-0401	4 mm	M8	+68/-100	8 mm	8,5 mm	9,5 mm	17 mm	5 mm
IK 420-0500	5 mm	M8	+68/-100	8 mm	8,5 mm	9,5 mm	17 mm	5 mm
IK 420-0600	6 mm	M10	+60/-100	10 mm	10,5 mm	12 mm	22 mm	6 mm
IK 420-0800	8 mm	M12	+92/-140	13 mm	13 mm	14 mm	24,5 mm	8 mm
IK 420-1000	10 mm	M16	+96/-180	18 mm	14,5 mm	15 mm	30 mm	10 mm
IK 420-1200	12 mm	M20	+120/-210	20 mm	19,3 mm	19,5 mm	38 mm	15 mm

## I-SYS IK-420 Swage & Eye Turnbuckle Fitted at Each End

Each assembly consists of;

- (variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
- (2 qty.) -Swaged External Thread Ends RH/LH (Model # 850/855)
- (2 qty.) -Eye with External Threads RH/LH (Model # 885/886)
- (4 qty.) -Hexagon Nuts RH/LH (Model # 892/893)
- (2 qty.) -Turnbuckle Barrels RH/LH (Model # 875)

Metric Fittings.  
Measurements given  
in Millimeters.

