

NIXALITE® OF AMERICA INC
 1025 16th Avenue, East Moline, IL 61244
 P 800.624.1189 WEB www.nixalite.com
 F 800.624.1196 EMAIL birdcontrol@nixalite.com

NOTE: Contact Nixalite before specifying Model W Nixalite. This is a specific use model.


Copyright© 2010 by Nixalite® of America Inc, East Moline, IL 61244 - All rights reserved.
 Nixalite® is a fully registered trademark of Nixalite® of America Inc.

PREMIUM NIXALITE® MODEL W


SCALE: 3"=1'0" UNLESS OTHERWISE NOTED




TOP VIEW

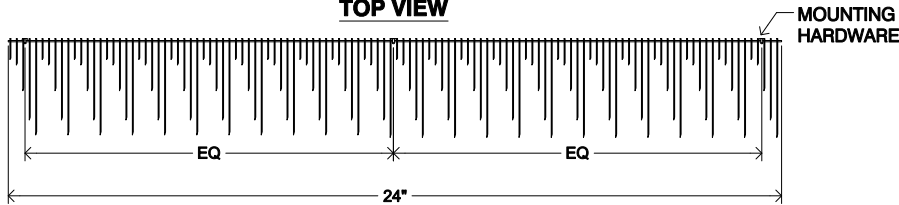


SIDE VIEW

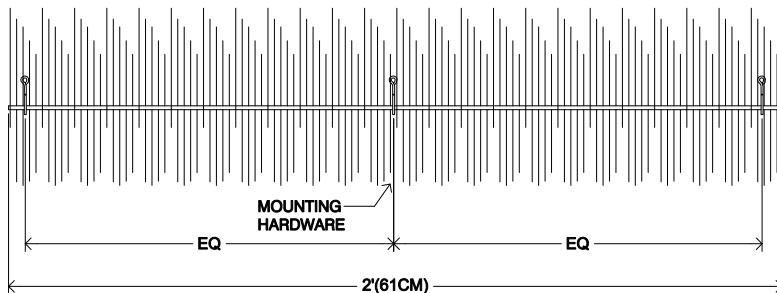

END VIEW

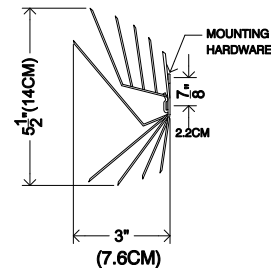

ISOMETRIC 12" (30.5CM)
 STRIP PREMIUM
 MODEL W
 NIXALITE

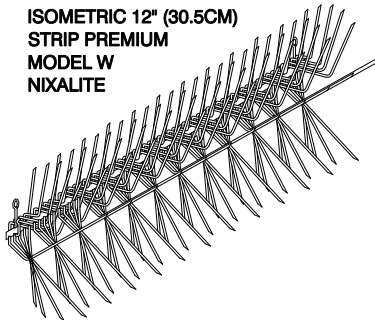

GENERAL NOTES


1. ALL PREMIUM NIXALITE SPIKE BARRIERS 100% HIGH GRADE STAINLESS STEEL WIRE AND STRIP - NO PLASTIC
2. PREMIUM MODEL W; 120 POINTS/12"(30.5CM) AND COMES IN 2'(61CM) AND 4'(122CM) STRIP LENGTHS.
2. **MADE IN THE USA**
3. **MOUNTING HARDWARE SUPPLIED WITH ALL PREMIUM NIXALITE MODELS**
4. ALL PREMIUM NIXALITE MODELS HAVE **20 YEAR WARRANTY**
5. **PREMIUM MODEL W IS VERTICAL SURFACES ONLY. USE ABOVE NARROW SURFACES LESS THAN 2" DEEP. USE WITH MODEL S NIXALITE TO CONTROL CLIMBING ANIMALS OR MUD NEST BUILDING BIRDS.**
6. 3-PART SPECS IN 3 FORMATS: www.nixalite.com/architectinfocenter.aspx OR CONTACT NIXALITE AT 800.624.1189

GENERAL NOTES

1. ALL PREMIUM NIXALITE SPIKE BARRIERS 100% HIGH GRADE STAINLESS STEEL WIRE AND STRIP - **NO PLASTIC**
2. **MADE IN THE USA**
3. **MOUNTING HARDWARE SUPPLIED WITH ALL PREMIUM NIXALITE MODELS**
4. ALL PREMIUM NIXALITE MODELS HAVE **20 YEAR WARRANTY**
5. **PREMIUM MODEL W IS VERTICAL SURFACES ONLY. USE ABOVE NARROW SURFACES LESS THAN 2" DEEP. USE WITH MODEL S NIXALITE TO CONTROL CLIMBING ANIMALS OR MUDNEST BUILDING BIRDS**
6. 3-PART SPECS IN PDF/DOC/TXT FORMATS:
www.nixalite.com/architectinfocenter.aspx
 OR CONTACT NIXALITE AT 800.624.1189


Above Narrow Surfaces

- A Max horizontal surface coverage is 2" in depth.
- B Maximum distance from center of base strip to horizontal surface is 3-3/4".
- C Max distance from horizontal surface to the mounting hardware is 3-5/8".
- D For this app. install Model W with the 6 wire side facing up.

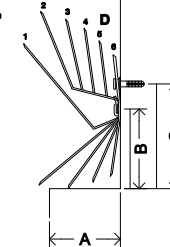


Climbing Animal Barrier

- Install 2 rows Model W (top and bottom) and 4 rows Model S (in between).
- A The top row of Model W to be 2-1/8" from overhead object.
- B Center to center spacing for all rows is 4-1/2".
- C 6-wire side of Model W points away from inside rows.
- D Lowest row to be 60" from ground (min).

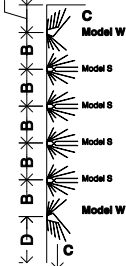


Mud Swallow Installation

- A Maximum distance from overhead surface to mounting hardware position is 6-1/4".
- B Maximum distance from overhead surface to Model W base strip center is 7-1/4".
- C At least one row of Model W and Model S are required. Some installations will require additional rows of both models.
- D For this app. install Model W with the 6 wire side facing up.

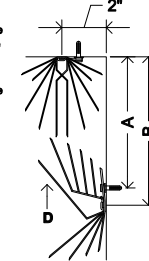

Row Cap

- Install Model W 'Row Cap' to protect exposed sides of Model S Nixalite below.
- B On curved surfaces, run all strips front-to-back.
- C Install Model W with the 6 wire side facing up. Space rows to eliminate gaps while preventing excessive wire crossing.

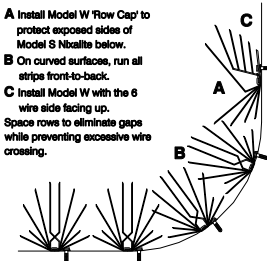

For more information on Nixalite's Premium Bird Barrier Spikes, go to:
www.nixalite.com/Nixalitemodels.aspx or contact Nixalite at 800.624.1189

Copyright© 2010 by Nixalite® of America Inc, East Moline, IL 61244 - All rights reserved.
 Nixalite® is a fully registered trademark of Nixalite® of America Inc.

PLANNING AND ESTIMATING - PLANNING AND ESTIMATING - PLANNING AND ESTIMATING - PLANNING AND ESTIMATING - PLANNING AND ESTIMATING